


Flexible Cables

HKAJ-Ø 300/500 V

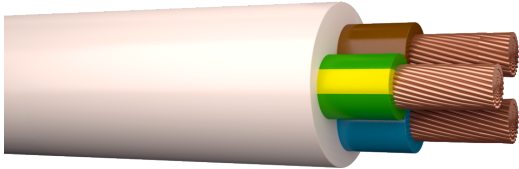

Application

Halogen-free, round flexible cable for connecting to devices and appliances indoors.

Standard

HD 21.14 S1
EN 60228
EN 61034-1-2
EN 50267-1
IEC 60332-1-2

Conductor standard

Halogen free material

Vertical flame propagation for a single insulated wire or cable

Construction

Cable Shape Round
Conductor Insulation Halogen free compound
Outer Sheath Halogen free compound

Temperature

Maximum operating Temperature max. 60°C
Minimum operating Temperature for cable type min. -15°C
[°C]
Temperatures at installation [°C] min. -15°C to 60°C

Features

Bending radius 6xD
RoHS declaration In compliance with RoHS and REACH

Electrical

Test Voltage [kV] 2000 V AC

Conductors and screen area [mm ²]	Outer Sheath Colour	Diameter over sheath [mm]	Cable weight [kg/km]	Delivery Package	EAN/GTIN number	Max current load in air [A]
3G0,75	White	6,6	55	C100	6430010752530	
3G1,0	White	6,9	65	C100	6430010751205	
3G1,5	White	8,3	90	C100	6430010751014	